


MCBQ* 外觀尺寸 $\phi 32\sim\phi 100$


氣壓缸附鎖定裝置



MCBQV

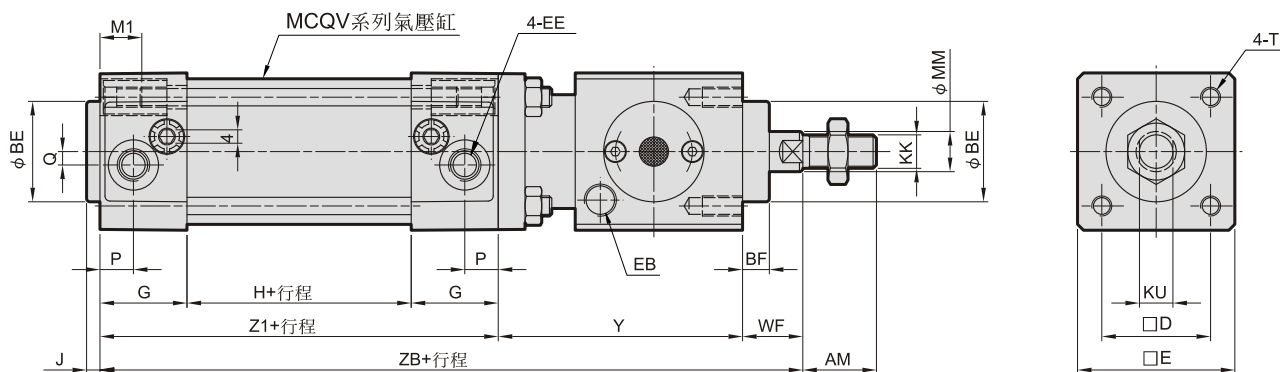

MCBQI

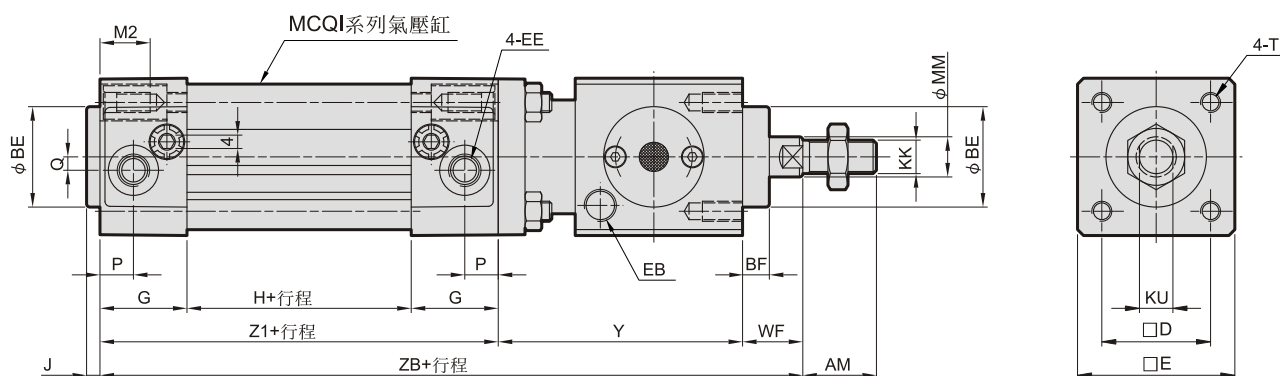

代號 內徑	AM	BE	BF	D	E	EB	EE	G	H	J	KK	KU	M1	M2	MM	P	Q	T	WF	Y	Z1	ZB
32	22	30	8	32.5	47	G 1/8	G 1/8	26	42	4	M10×1.25	10	12	15	12	13	4	M6×12	18	73	94	185
40	24	35	8	38	53	G 1/8	G 1/4	30	45	4	M12×1.25	13	12	15	16	15	4	M6×12	18	76	105	199
50	32	40	8	46.5	65	G 1/8	G 1/4	30	46	4	M16×1.5	16	16	18	20	15	4	M8×14	20	90	106	216
63	32	45	10	56.5	75	G 1/8	G 3/8	32	57	4	M16×1.5	16	16	18	20	16	7	M8×14	22	92	121	235
80	40	45	10	72	95	G 1/4	G 3/8	38	52	6	M20×1.5	21	18	19	25	19	7	M10×16	24	110	128	262
100	40	55	10	89	115	G 1/4	G 1/2	40	58	6	M20×1.5	21	18	19	25	20	7	M10×16	26	130	138	294

