


■ Low-pressure hydraulic cylinders :

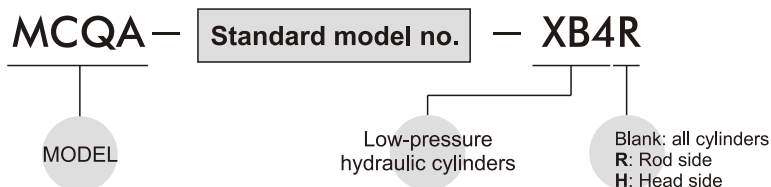


Applicable series:

Series	Model
Standard cylinders	MCQA, MCQV, MCQI (for tube I.D. ϕ 32~ ϕ 100)
Miniature cylinders	MCMA, MCMB, MCM I (for tube I.D. ϕ 16~ ϕ 40)
Guide cylinder	MGTB, MGTK, MGTU, MGTX

Note : 1. Piston packing : Double U-type.
2. To make sure the dimenstions after ordered.

■ Low friction cylinders :

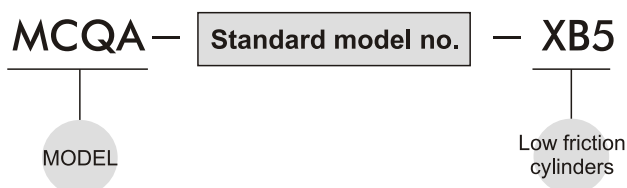


Applicable series:

Series	Model
Standard cylinders	MCQA, MCQV, MCQI, MCQN
Compact cylinders	MCJA, MCJQ, MCJT, MCJS, MCJK
Miniature cylinders	MCMA, MCMB, MCM I
Round cylinders	MCCG, MCCN
Guide cylinder	MGTB, MGTK, MGTU, MGTX

Note : It's not suitable for the bore which is under ϕ 12 or over ϕ 150.

■ Heat resistant cylinders :

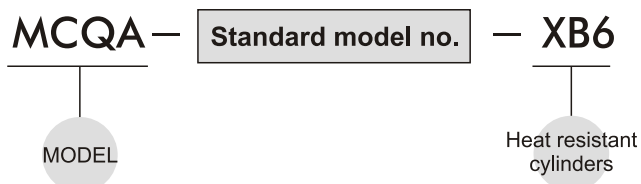

Applicable series:

Series	Model
Standard cylinders	MCQA, MCQV, MCQI
Compact cylinders	MCJA, MCJQ, MCJT, MCJS, MCJK
Miniature cylinders	MCMA, MCMB, MCM I
Round cylinders	MCCG
Guide cylinder	MGTX

Note : 1. Seals materials: Fluoro rubber.
2. Ambient temperature: $-10\sim+150^{\circ}\text{C}$ (No freezing)
3. Auto switch: Can't mount.