



φ 16, φ 20


N type: φ 16~φ 40

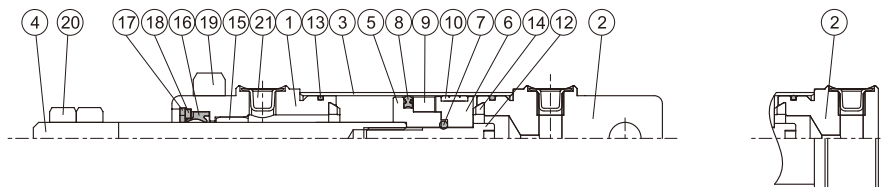

φ 25

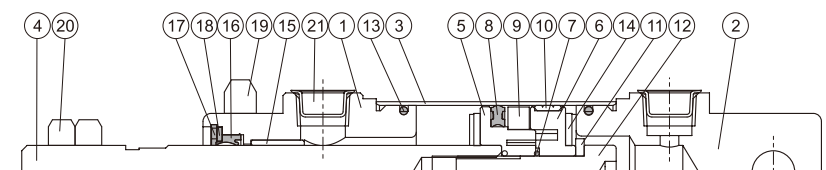

φ 32, φ 40

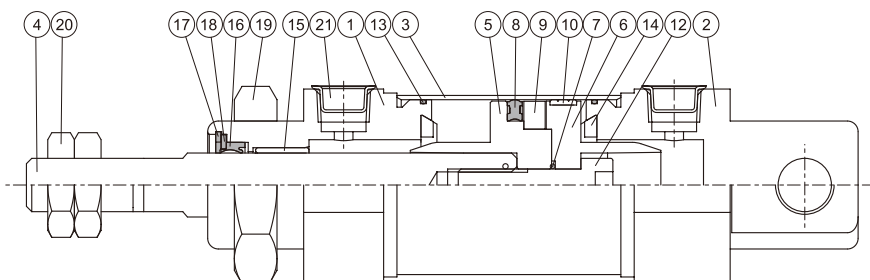

Material

No.	Tube I.D. Part name	16	20	25	32	40	Q'y		Componentn parts (inclusion)		Repair kits (inclusion)
							11 type	21 type	11 type	21 type	
1	Rod cover	Aluminum alloy					1	2	●	●	
2	Head cover	Aluminum alloy					1	—	●		
3	Tube	Stainless steel					1	1			
4	Piston rod	※1	Carbon steel				1	1			
5	Piston-R	Aluminum alloy		※2	Aluminum alloy		1	1	●	●	
6	Piston-H	Aluminum alloy		※2	Aluminum alloy		1	1	●	●	
7	Piston gasket	NBR					1	1	●	●	
8	Piston packing	NBR					1	1	●	●	
9	Magnet ring	Magnet material					1	1	●	●	
10	Wear ring	Teflon + Graphite					1	1	●	●	
11	Washer	—		※3	—		1	—	●		
12	Piston bolt	SCM					1	—	●		
13	Cover ring	NBR					2	2	●	●	
14	Cushion gasket	NBR					2	2	●	●	
15	Rod bush	Bearing alloy					1	2	●	●	
16	Rod packing	NBR					1	2	●	●	●
17	Snap ring	Spring steel					1	2	●	●	
18	Washer	Carbon steel					1	2	●	●	
19	Tie nut	Carbon steel					1	2	●	●	
20	Rod front nut	Carbon steel					2	2	●	●	
21	Port plug	Plastic					2	2	●	●	

※1. Stainless steel ※2. Polyurethane ※3. Carbon steel

Order example of component parts / repair kits

Tube I.D.	Component parts	Repair kits
φ 16	CP-MCMA-16	PS-MCMA-16
φ 20	CP-MCMA-20	PS-MCMA-20
φ 25	CP-MCMA-25	PS-MCMA-25
φ 32	CP-MCMA-32	PS-MCMA-32
φ 40	CP-MCMA-40	PS-MCMA-40

Non-pivot type (end-plain)

Tube I.D.	Component parts
φ 16	CP-MCMA-16-N
φ 20	CP-MCMA-20-N
φ 25	CP-MCMA-25-N
φ 32	CP-MCMA-32-N
φ 40	CP-MCMA-40-N