


MCMB Inside structure & Parts list / Cushion pad



MINIATURE CYLINDERS

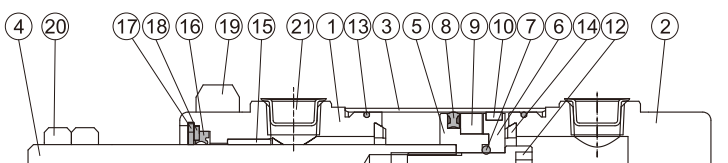

φ 20, φ 40





φ 25

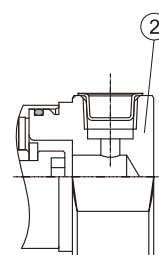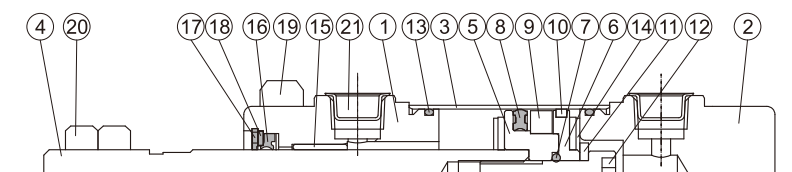

N type: φ 20~φ 40

φ 32

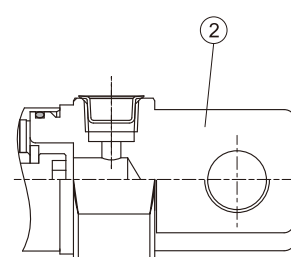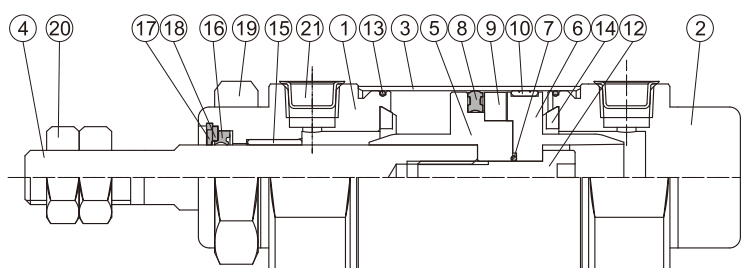

E type: φ 20~φ 40

Material

No.	Part name	Tube I.D.				Q'ty		Component parts (inclusion)		Repair kits (inclusion)
		20	25	32	40	11 type	21 type	11 type	21 type	
1	Rod cover	Aluminum alloy				1	2	●	●	
2	Head cover	Aluminum alloy				1	—	●	●	
3	Tube	Stainless steel				1	1			
4	Piston rod	Carbon steel				1	1			
5	Piston-R	Aluminum alloy				1	1	●	●	
6	Piston-H	Aluminum alloy				1	1	●	●	
7	Piston gasket	NBR				1	1	●	●	
8	Piston packing	NBR				1	1	●	●	
9	Magnet ring	Magnet material				1	1	●	●	
10	Wear ring	Teflon + Graphite				1	1	●	●	
11	Washer	—	※1	—	—	1	—	●	●	
12	Piston bolt	SCM				1	—	●	●	
13	Cover ring	NBR				2	2	●	●	
14	Cushion gasket	NBR				2	2	●	●	
15	Rod bush	Bearing alloy				1	2	●	●	
16	Rod packing	NBR				1	2	●	●	●
17	Snap ring	Spring steel				1	2	●	●	
18	Washer	Carbon steel				1	2	●	●	
19	Tie nut	Carbon steel				1	2	●	●	
20	Rod front nut	Carbon steel				2	2	●	●	
21	Port plug	Plastic				2	2	●	●	

※1. Carbon steel

Order example of component parts / repair kits

Tube I.D.	Component parts	Repair kits
φ 20	CP-MCMB-20	PS-MCMB-20
φ 25	CP-MCMB-25	PS-MCMB-25
φ 32	CP-MCMB-32	PS-MCMB-32
φ 40	CP-MCMB-40	PS-MCMB-40

Non-pivot type (end-plain)

Tube I.D.	Component parts
φ 20	CP-MCMB-20-N
φ 25	CP-MCMB-25-N
φ 32	CP-MCMB-32-N
φ 40	CP-MCMB-40-N

Pivot type

Tube I.D.	Component parts
φ 20	CP-MCMB-20-E
φ 25	CP-MCMB-25-E
φ 32	CP-MCMB-32-E
φ 40	CP-MCMB-40-E

