



$\phi 20$

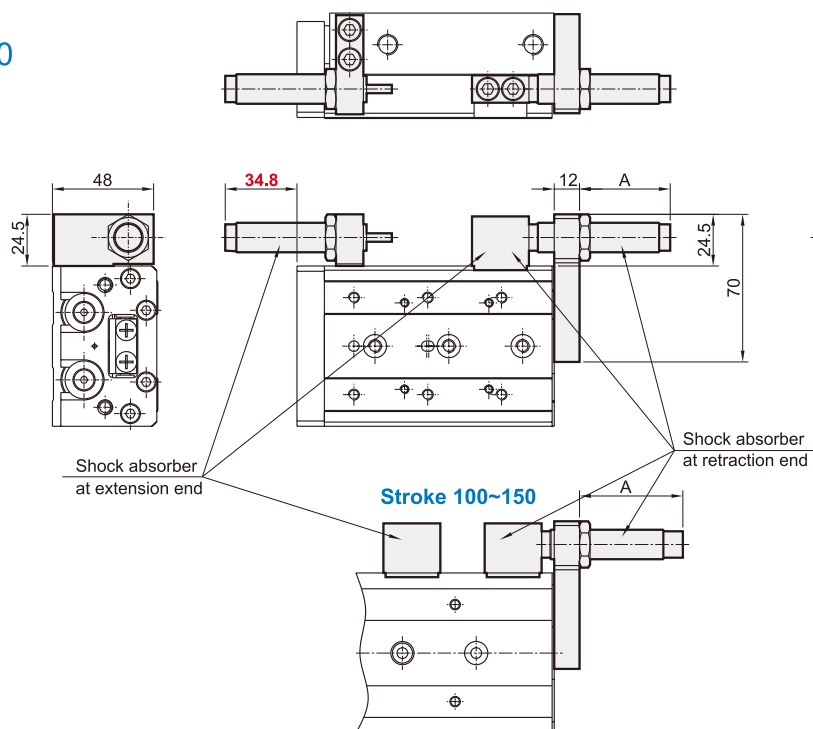

Stroke	Stroke adjustment range		A dimension (Retracted side mounting)
	Extending	Retracting	
10	Max. <b>40.3</b>	<b>15.8</b>	<b>28.8</b>
20		<b>25.8</b>	<b>38.8</b>
30		<b>35.8</b>	<b>48.8</b>
40		<b>35.8</b>	<b>48.8</b>
50		<b>30.8</b>	<b>43.8</b>
75		<b>16.8</b>	<b>29.8</b>
100		<b>36.8</b>	<b>49.8</b>
125		<b>36.8</b>	<b>49.8</b>
150		<b>36.8</b>	<b>49.8</b>

※ Other dimensions not indicated are the same as the basic style.

$\phi 25$

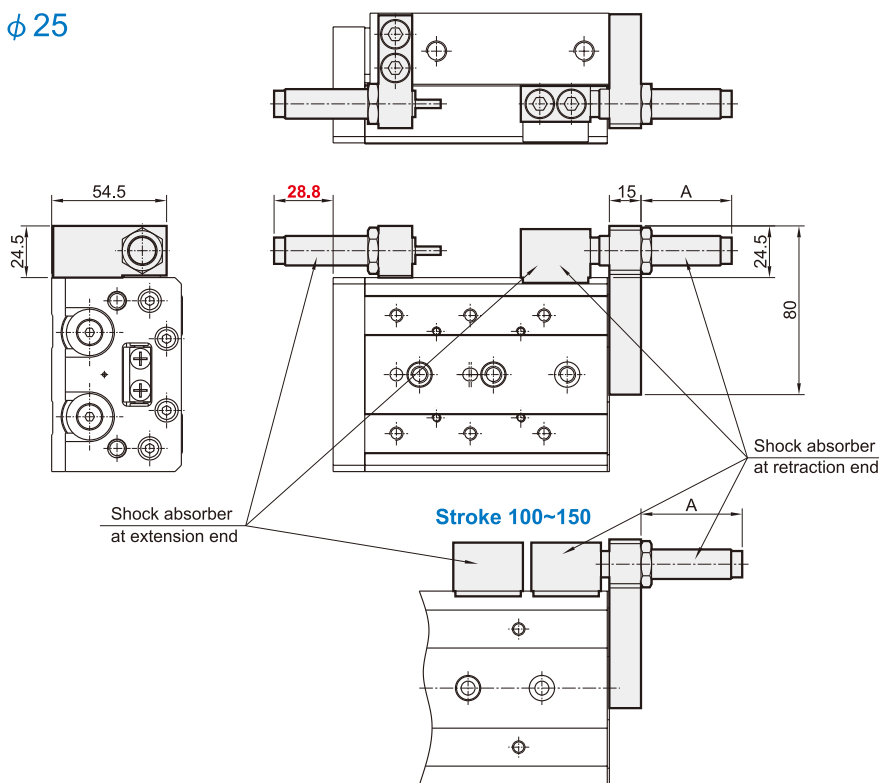

Stroke	Stroke adjustment range		A dimension (Retracted side mounting)
	Extending	Retracting	
10	Max. <b>36.3</b>	<b>12.8</b>	<b>26.8</b>
20		<b>22.8</b>	<b>36.8</b>
30		<b>32.8</b>	<b>46.8</b>
40		<b>32.8</b>	<b>46.8</b>
50		<b>29.8</b>	<b>43.8</b>
75		<b>13.8</b>	<b>27.8</b>
100		<b>34.8</b>	<b>48.8</b>
125		<b>32.8</b>	<b>46.8</b>
150		<b>32.8</b>	<b>46.8</b>

※ Other dimensions not indicated are the same as the basic style.