


MCHK Dimensions 20~50

COMPACT TYPE 3-FINGER GRIPPERS

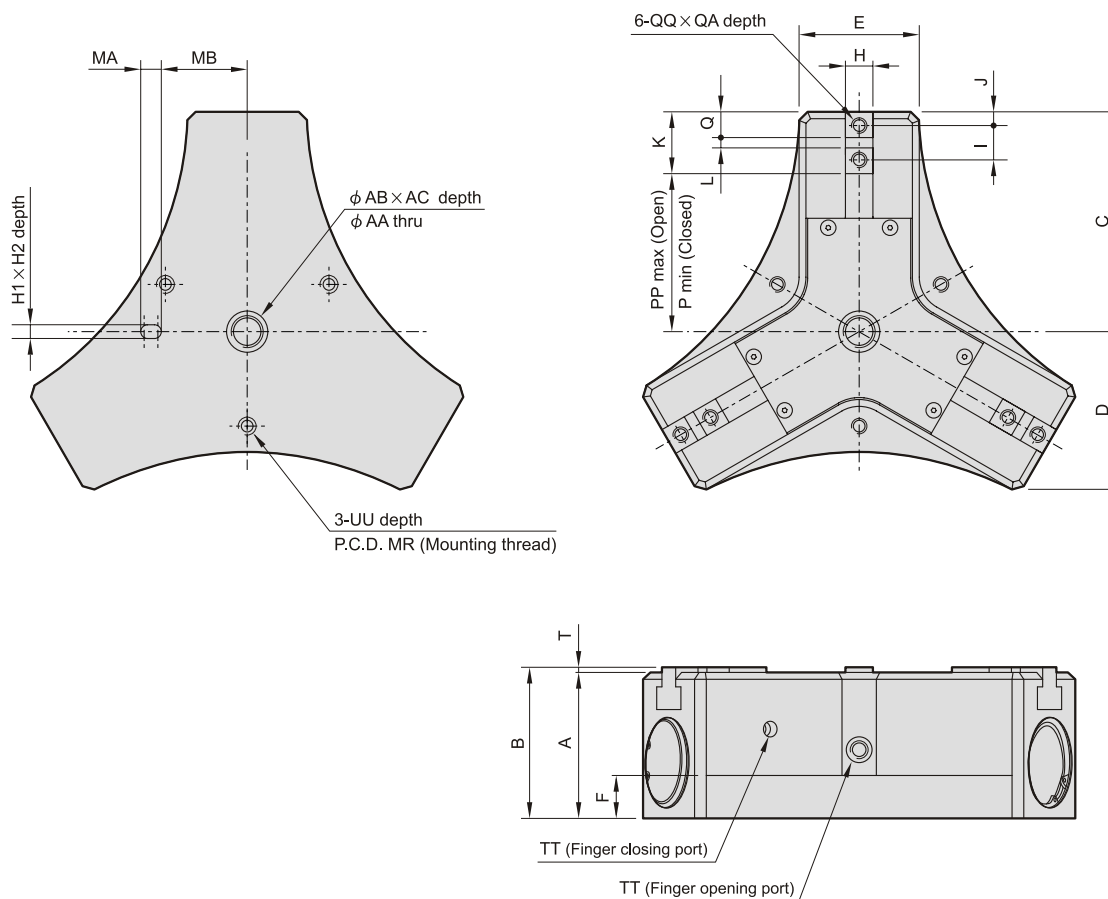

Code Model	A	AA	AB	AC	B	C	D	E	F	H	H1	H2	I	J	K	L	MA	MB	MR	P	PP	Q	QA
MCHK-20	39.5	8	8	4	42.5	58	43.9	38	9	8 ^{+0/-0.015}	4 ^{+0.03/-0}	4	12	4.5	21	3 ^{+0.03/-0}	5	27.5	60	27	37	9	8
MCHK-32	56	12	12	5	59	83.5	62	52	12	12 ^{+0/-0.018}	5 ^{+0.03/-0}	5	16	5.5	27	5 ^{+0.03/-0}	6	36	78	38.3	54.3	11	12
MCHK-50	85	16	24	5	88	128	91	70	15	16 ^{+0/-0.018}	8 ^{+0.03/-0}	5	20	8	36	6 ^{+0.03/-0}	10	50	110	67	92	15	16

Code Model	QQ	T	TT	UU
MCHK-20	M5×0.8	3	M5×0.8	M6×1.0
MCHK-32	M6×1.0	3	M5×0.8	M8×1.25
MCHK-50	M8×1.25	3	Rc1/8	M8×1.25