



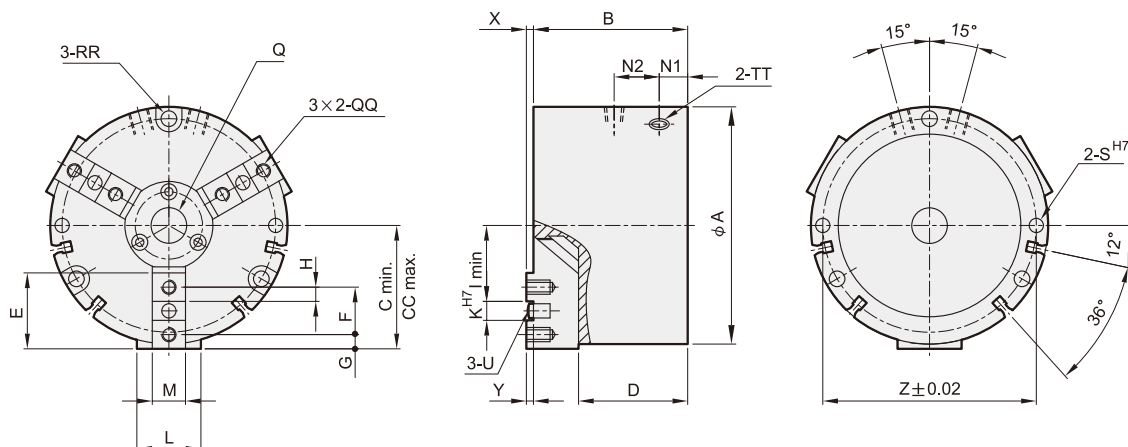

Code Model	A	B	C	CC	D	E	F	G	H	I	K	L	M	N1	N2	Q	QQ
MCHGH-64	64	47.5	33	37	32	18	12	3	3.5	22	5	17	10.2	10	16.5	7.5	M3×0.5 DP 8
MCHGH-80	80	56.5	42	48	39.5	21	13	4	4	29	5	23	12.2	10	22	15	M4×0.7 DP 9
MCHGH-100	100	65	52	60	46	25	16	5	5	36	6	27	14.2	12	24	20	M5×0.8 DP 12
MCHGH-125	125	76	65	75	53.5	32	20	6	6	45	8	30	16.2	13.5	28.5	25	M6×1.0 DP 12
MCHGH-160	160	94	84	97	67	40	24	8.5	8	59	8	40	20.2	17	36.5	36.5	M6×1.0 DP 12

Code Model	P	RR	S	TT	U	X	Y	Z
MCHGH-64	0.5	φ 4.5 thru, φ 8 C/B DP 6 P.C.D 56	φ 4 DP 10	M5	φ 4	1	2.5	56
MCHGH-80	1.2	φ 6.6 thru, φ 11 C/B DP 7 P.C.D 70	φ 4 DP 10	M5	φ 5	2	3	70
MCHGH-100	1.2	φ 6.6 thru, φ 11 C/B DP 7 P.C.D 90	φ 5 DP 12	M5	φ 6	2	3	90
MCHGH-125	1.2	φ 9 thru, φ 15 C/B DP 9 P.C.D 112	φ 6 DP 16	Rc1/8	φ 6	2	3.5	112
MCHGH-160	—	φ 9 thru, φ 15 C/B DP 9 P.C.D 146	φ 6 DP 20	Rc1/8	φ 6	2	4	146

Finger blanks

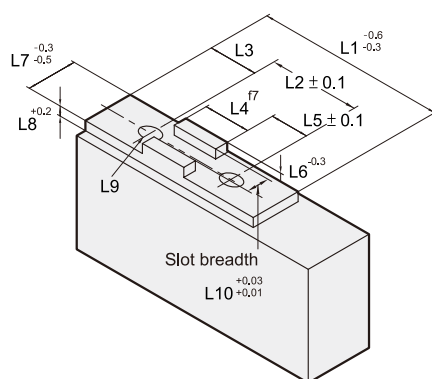

Code Model	L1	L2	L3	L4	L5	L6	L7	L8	L9	L10
MCHGH-64	18	12	3	5	3.5	2	10	—	φ 3.4	4
MCHGH-80	21	13	4	5	4	2.5	12	4.5	φ 4.5	4
MCHGH-100	25	16	5	6	5	3	14	5.5	φ 5.5	5
MCHGH-125	32	20	6	8	6	3	16	5.5	φ 6.6	6
MCHGH-160	40	24	8.5	8	8	3.5	20	5.5	φ 6.6	6