

2024年04月02日

## MACP302/401/403、MAFR302/401/403 系列 新增搭配截止閥規格(-HR/1\*/2\*/4\*)設變通知

感謝您支持與推廣金器產品，下列產品規格將進行變更，抱歉造成您的困擾，敬請理解配合。

1. 產品型號

MACP302/401/403、MAFR302/401/403

2. 變更理由

因市場銷售反應，新增搭配 MVHR 截止閥規格(-HR/1\*/2\*/4\*)。

3. 變更內容

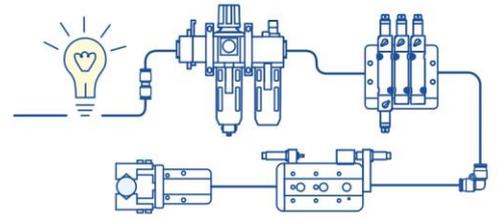
詳見次頁。

4. 變更實施日期

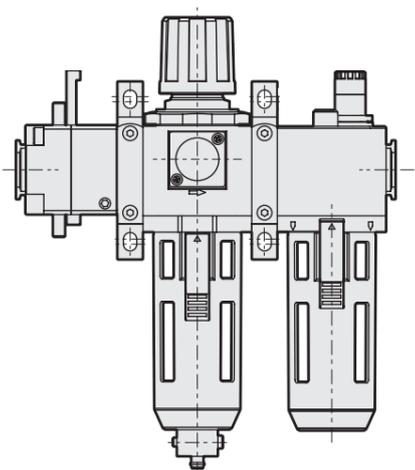
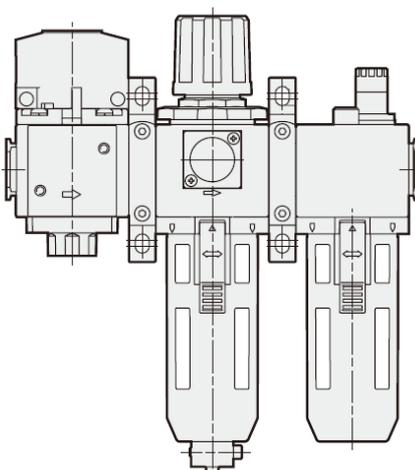
即日起。

5. 其他

如有其他疑問，請洽詢公司營業單位。



以 MACP302 為例。

設變前	設變後
<b>外觀</b>	
	
<b>規格</b>	
<p><b>訂購代號</b> MACP302 - 8A - NC□□ - E1 - □ - HT - □</p> <ul style="list-style-type: none"> <li>型號</li> <li>配管口徑代號 8A: 1/4 10A: 3/8 15A: 1/2</li> <li>(選用) 數位壓力傳感器 E1: MP41P-022 E2: MP41P-022-QD E5: MP41P-042 E6: MP41P-042-QD <small>*MP41 規格，請參 5-13 頁。</small></li> <li>過濾精度 無: 5µm 40u: 40µm</li> <li>截止閥 HT: MVHT-302-3H <small>*MVHT 規格，請參 3-69 頁。</small></li> <li>配管口螺牙 無: Rc 牙 G: G 牙 NPT: NPT 牙</li> </ul> <p style="text-align: center;">- HT</p> <p style="text-align: center;">截止閥 HT: MVHT-302-3H <small>*MVHT 規格，請參 3-69 頁。</small></p>	<p><b>訂購代號</b> MACP302 - 8A - NC□□ - E1 - □ - HR - □</p> <ul style="list-style-type: none"> <li>型號</li> <li>配管口徑代號 8A: 1/4 10A: 3/8 15A: 1/2</li> <li>(選用) 數位壓力傳感器 E1: MP41P-022 E2: MP41P-022-QD E5: MP41P-042 E6: MP41P-042-QD <small>*MP41 規格，請參 5-13 頁。</small></li> <li>過濾精度 無: 5µm 40u: 40µm</li> <li>截止閥 HR: MVHR-302-3H 1: MVHR-302S-3H-AC110 1L: MVHR-302S-3H-AC110-L 1E: MVHR-302S-3H-AC110-E 2: MVHR-302S-3H-AC220 2L: MVHR-302S-3H-AC220-L 2E: MVHR-302S-3H-AC220-E 4: MVHR-302S-3H-DC24 4L: MVHR-302S-3H-DC24-L 4E: MVHR-302S-3H-DC24-E <small>*MVHR 規格，請參 3-71 頁。</small></li> <li>配管口螺牙 無: Rc 牙 G: G 牙 NPT: NPT 牙</li> </ul> <p style="text-align: center;">- HR</p> <p style="text-align: center;">截止閥 HR: MVHR-302-3H 1: MVHR-302S-3H-AC110 1L: MVHR-302S-3H-AC110-L 1E: MVHR-302S-3H-AC110-E 2: MVHR-302S-3H-AC220 2L: MVHR-302S-3H-AC220-L 2E: MVHR-302S-3H-AC220-E 4: MVHR-302S-3H-DC24 4L: MVHR-302S-3H-DC24-L 4E: MVHR-302S-3H-DC24-E <small>*MVHR 規格，請參 3-71 頁。</small></p>