


MP* 系列 柱塞 (公頭)


快速接頭




MPM (外牙型)

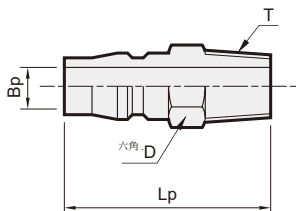


MPF (內牙型)

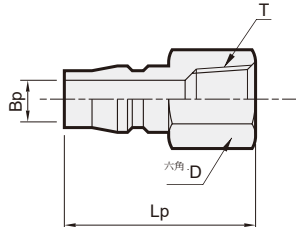

MPH (軟管接頭型)

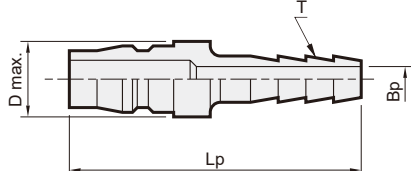

MPP (螺帽型)

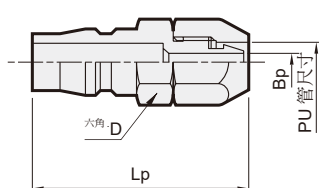

訂購代號

MPM - 20 - S

20
30
40

S: 鋼材
B: 銅材

型號

MPM	
MPF	
MPH	
MPP	

型號	螺牙尺寸 T	尺寸 (mm)			重量 (g)	
		Bp	D	Lp	鋼	銅
MPM-20	R1/4	ø7.5	14/16.2	41	25	27
MPM-30	R3/8	ø7.5	17/19.6	43	40	45
MPM-40	R1/2	ø7.5	21/24.2	46	65	70

型號	螺牙尺寸 T	尺寸 (mm)			重量 (g)	
		Bp	D	Lp	鋼	銅
MPF-20	Rc1/4	ø7.5	17/19.6	38	30	32
MPF-30	Rc3/8	ø7.5	21/24.2	41	45	48
MPF-40	Rc1/2	ø7.5	26/30	43	65	70

型號	軟管尺寸 T	尺寸 (mm)			重量 (g)	
		Bp	D max.	Lp	鋼	銅
MPH-20	5/16"Hose	ø5	ø16	58	27	29
MPH-30	3/8"Hose	ø7.5	ø16	62	35	38
MPH-40	1/2"Hose	ø7.5	ø18	64	50	55

型號	PU 尺寸 內徑 × 外徑 (mm)	尺寸 (mm)			重量 (g)	
		Bp	D	Lp	鋼	銅
MPP-20	5×8	ø4	14/16.2	42.5	30	33
MPP-30	6.5×10	ø5	16/18.2	44.5	40	43
MPP-40	8×12	ø6	17/19.2	45	40	43