


MVSB-180 系列


電磁閥

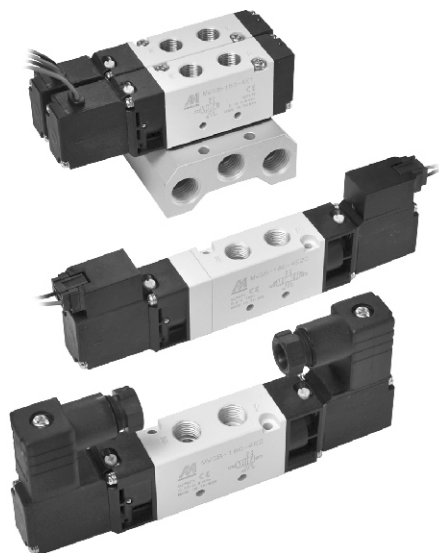


規格：

型號	4E1	4E2	4E2C.P.R
配管口徑代號	6A		
配管口徑尺寸	Rc1/8		
方口數	5口		
位置數	2位置	2位置	3位置
使用流體	空氣		
使用壓力範圍	0.15~0.8 MPa		0.2~0.7 MPa
耐壓力	1 MPa		
有效斷面積	12 mm ²	12 mm ²	9 mm ²
周圍溫度	-5~+50°C (不凍結)		
應答時間	30 ms		
定格電壓	AC110V, 220V (50/60)Hz, DC24V		
電力消耗	AC=2.1/1.8VA DC=1.6W		
電壓容許範圍	±10%		
絕緣等級	B 級		
重量	100 g	143 g	155 g

閥 / 訂購代號：

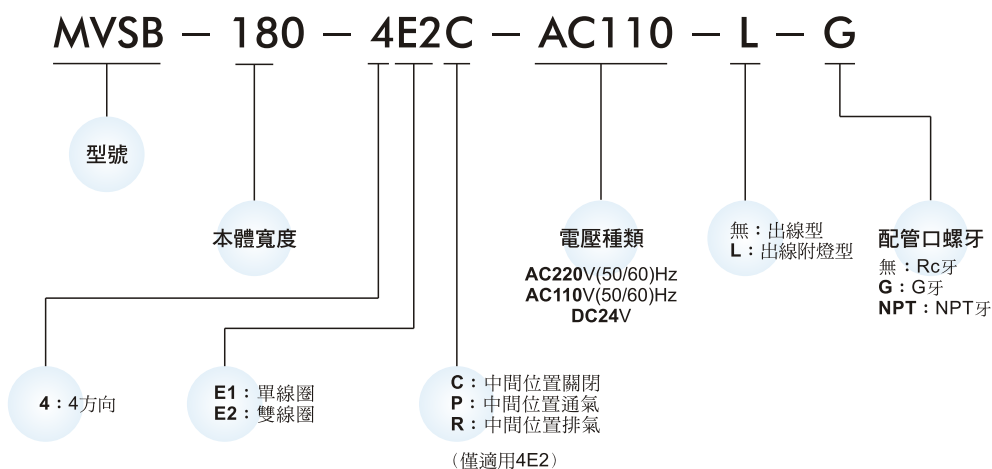

連座 / 訂購代號：

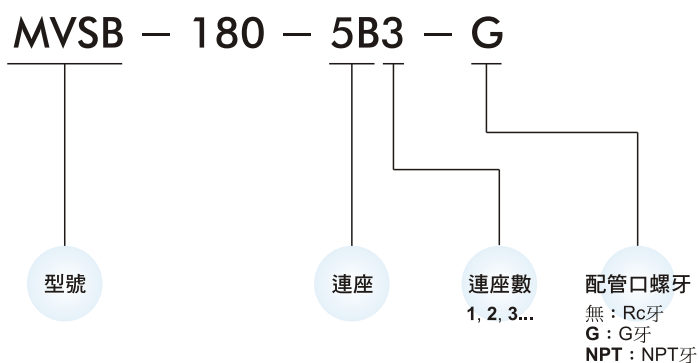


Mindman

MVSB-180 外觀尺寸


電磁閥



MVSB-180-4E1

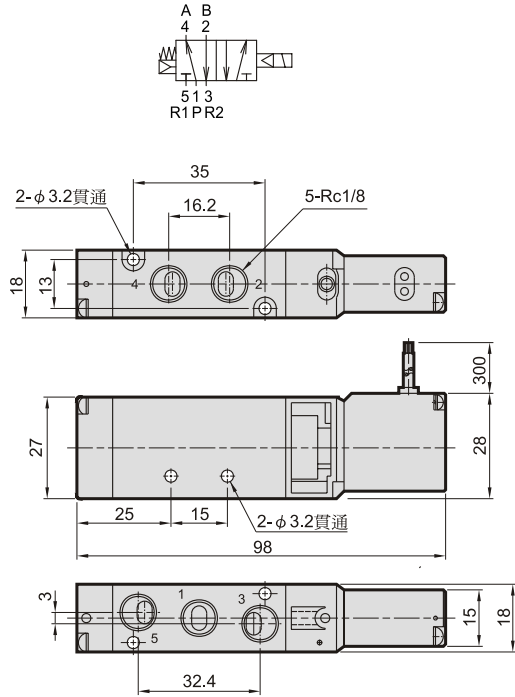


MVSB-180-4E2

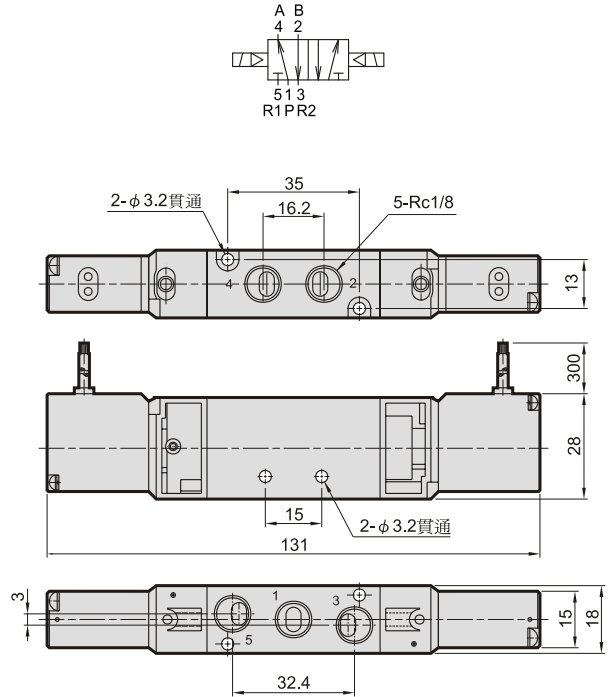


MVSB-180-4E2C.P.R



MVSB-180-4E2C

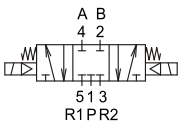


MVSB-180-4E2P

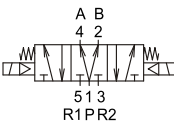

MVSB-180-4E2R

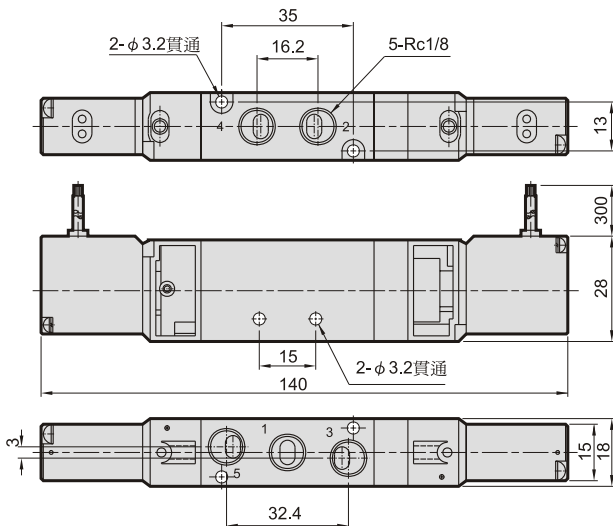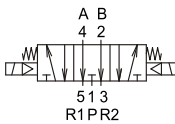

流量特性圖：

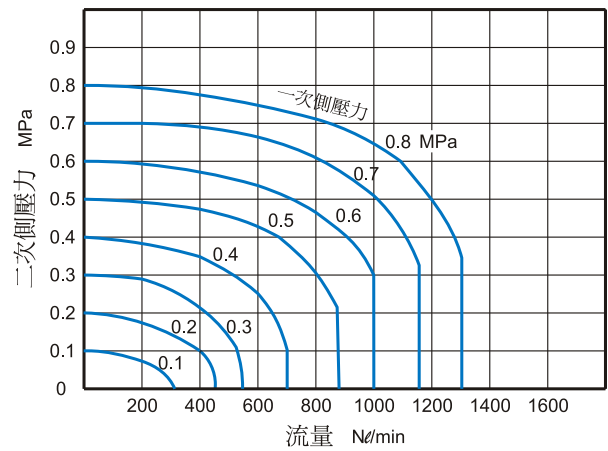





Mindman

MVSB-180 出線附燈型





電磁閥



MVSB-180-4E1-L

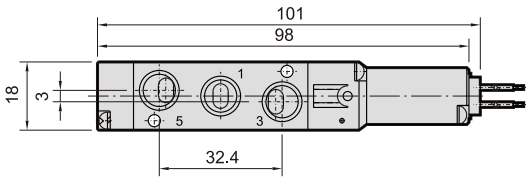
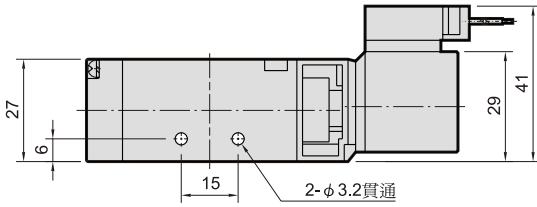
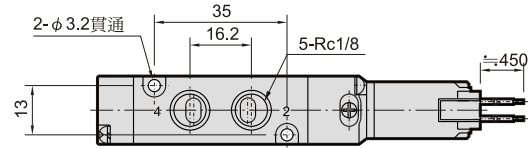
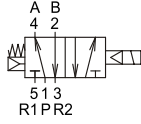


MVSB-180-4E2-L

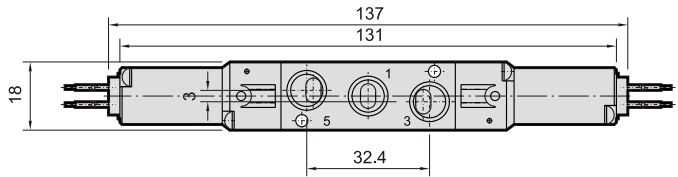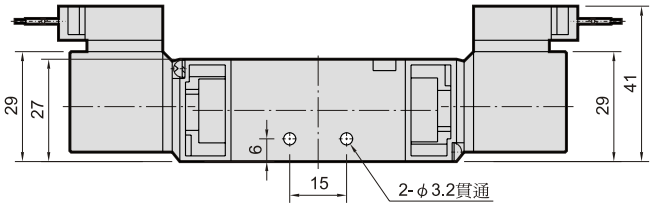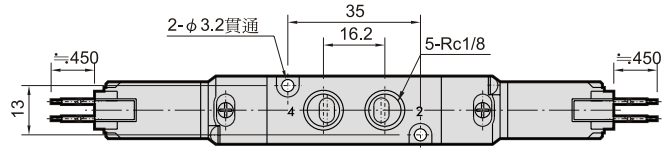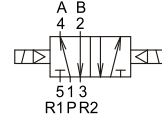

MVSB-180-4E2C.P.R-L

MVSB-180-4E2C-L MVSB-180-4E2P-L MVSB-180-4E2R-L

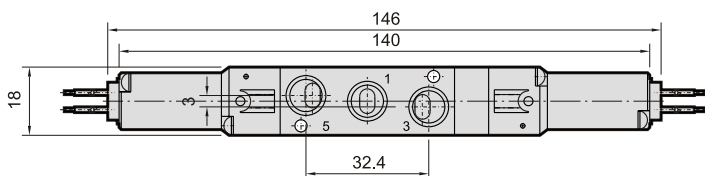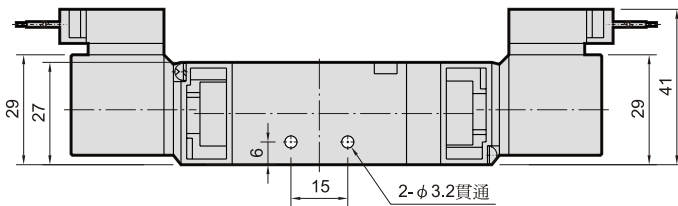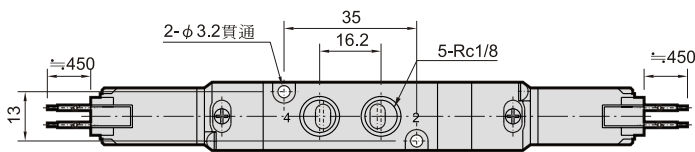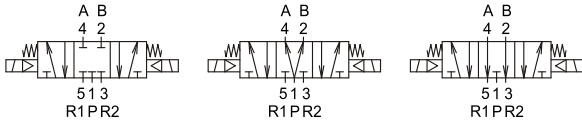


Mindman

MVSB-180 連座

電磁閥



MVSB-180-5B*

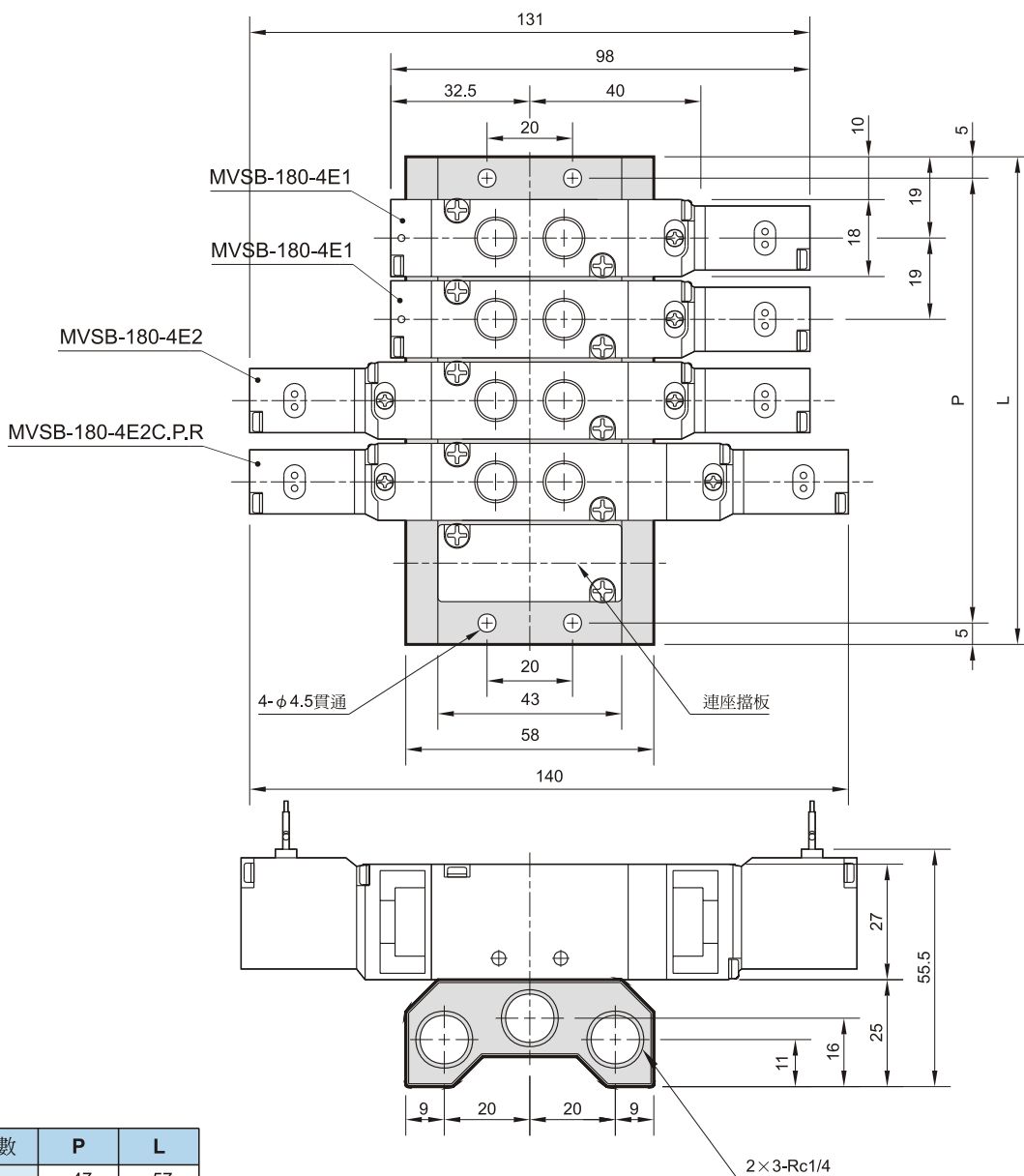

連座數	P	L
2	47	57
3	66	76
4	85	95
5	104	114
6	123	133
7	142	152
8	161	171
9	180	190
10	199	209

