
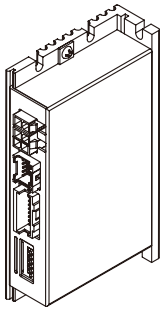
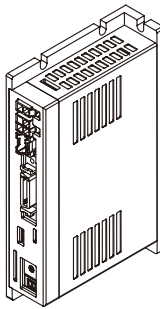
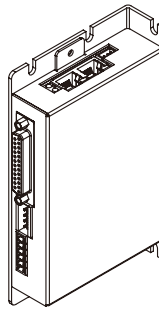


Controllers Selector Table

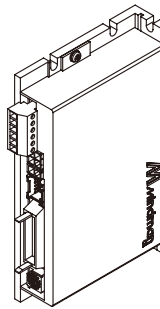

ELECTRIC CYLINDER CONTROLLER

Mindman

Model	MECP	MECQ1	CM20	CK10
Fig				
Stepper motor type	SM	SM	BM	SM
Pulse	Single / Double	–	Single / Double	Single / Double / AB quadrature
I/O	Input	4	5	12
	Output	4	4	10
Feature	I/O function	–	1. Definable I/O 2. Programmable motion control function (Parameter)	1. Definable I/O 2. Programmable motion control function (Position Table)
	Communication	–	Plus-R, DLL function(PC base)	Plus-R, DLL function(PC base), Modbus
	Interface	–	RS485	RS485
	Mode	Position control Velocity control	Position control Velocity control Torque control	Position control Velocity control
Input power	DC 24V		DC 24V~48V	Control: DC 24V Motor drive: DC 24V~48V
Dimension W×H×D (mm)	115.5×66×25.3	134×83×26.5	146×86.6×28.4	134×83.3×26.5