

M12*-SF / SM series

CONNECTOR (FEMALE / MALE)



mindman



Specification

Model	M124A-SF	M124A-SM	M124D-SM	
Male pin out				
Number of contacts	4			
Code	A	A	D	
Rated voltage	250V DC/AC			
Rated current	4A			
Temperature	-25°C~+80°C (No freezing)	-40°C~+105°C (No freezing)		
Protection class of contact	IP 67			
Suitable for AWG	22AWG			
Seals for cable OD	ø5.5 mm	ø4 mm ~ ø8 mm		
Housing material	Nylon			

Order example

M124 A — SM


MODEL
M124:
M12, 4 Pin

CODE	CONNECTOR
A	A-coded SF: Straight female SM: Straight male
D	D-coded SM: Straight male

Dimensions


A-coded

M124A-SM

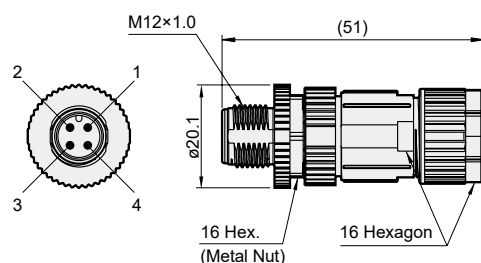

D-coded

M124D-SM

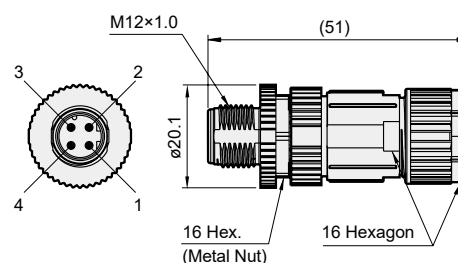

M124A-SF

