

M124A-** series

CABLE WITH CONNECTOR (FEMALE – MALE / LEAD WIRE)



M124A-SFSM



M124A-SFW



M124A-LFW

Specification

Model	M124A-SFSM		M124A-*FW
Female pin out			
Number of contacts	4	4	4
Rated voltage	125V DC/AC		
Rated current	3A		
Contact material	Brass (Au plating)		
Contact bearer material	PVC		
Housing color	Gray		
Cable material	ø4.2, PVC		ø5, PVC
Cable color	Gray		
Temperature	-20°C~+60°C (No freezing)		-20°C~+80°C (No freezing)
Cable conductor	22AWG		22AWG
Protection class of contact	IP67		

Order example

M124 A – SFSM – PVC – 3M


Model	Code	Connector	Cable material	Cable length
M124	M12, 4 Pin	A: A-coded	SFSM: Straight female - Straight male	PVC: ø4.2 PVC
			SFW: Straight female - Lead wire	PVC: ø5 PVC
			LFW: Angle female - Lead wire	PVC: ø5 PVC
				3M: 3000 mm
				1M: 1000 mm
				3M: 3000 mm

M12A-** Dimensions

CABLE WITH CONNECTOR (FEMALE – MALE / LEAD WIRE)




M12A-SFSM

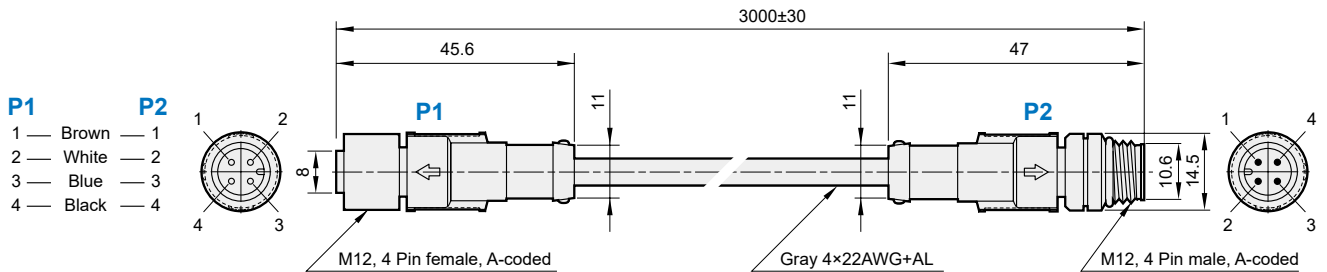

M12A-SFW

Straight

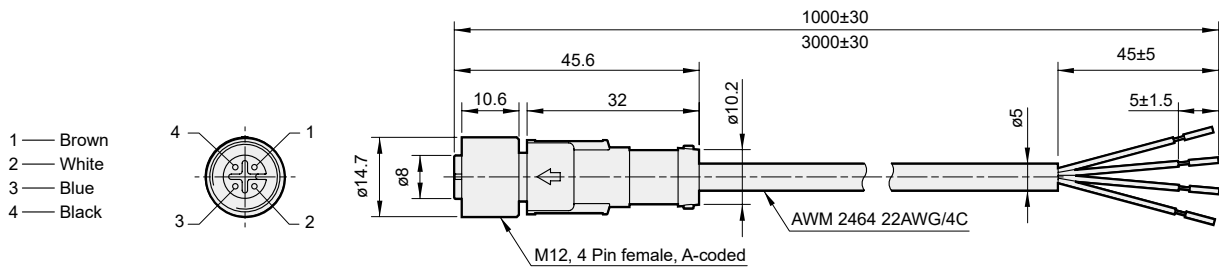

M12A-LFW

Angle

