


M125B-SFW series

CABLE WITH CONNECTOR (FEMALE – LEAD WIRE)

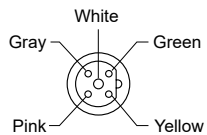

Specification

Model	M125B-SFW
Female pin out	
Number of contacts	5
Rated voltage	125V DC/AC
Rated current	3A
Contact material	Brass (Au plating)
Contact bearer material	PVC
Housing color	Gray
Cable material	ø5.5, PVC
Cable color	Gray
Temperature	-20°C~+60°C (No freezing)
Cable conductor	24AWG
Protection class of contact	IP 67

Order example

M125B – SFW – PVC – 2M

MODEL
M125: M12, 5 Pin

B: B-coded

CABLE MATERIAL
PVC: ø5.5 PVC

CABLE LENGTH
2M: 2000 mm

CONNECTOR

SFW: Straight female – Lead wire

Dimension

P1

- 1 Yellow
- 2 Green
- 3 Gray
- 4 Pink
- 5 Brown
- White

