



M83-SFSM

 
 
 
 
 
 
 


M83/84-SFW



M83/84-LFW

Specification

Model	M83-SFSM		M83-SFW M83-LFW		M84-SFW M84-LFW		M88-SFW
Female pin out							
Number of contacts	3	3	3		4		8
Rated voltage	125V DC/AC		60V DC/AC		60V DC/AC		30V DC
Rated current	3A		3A		3A		1.5A
Contact material	Brass (Au plating)						
Contact bearer material	PVC		PA		PA		PA
Housing material	-		PP		PP		PA
Housing color	Gray		Black		Black		Black
Cable material	ø3.5 PVC		ø4.5 PVC	ø4.5 PUR	ø4.5 PVC	ø4.5 PUR	ø5 PVC
Cable color	Gray		Gray	Black	Gray	Black	Black
Temperature (No freezing)	-20°C~+60°C		-20°C~+80°C				
Cable conductor	24AWG						26AWG
Protection class	IP67						

Order example

M83 – SFW – PVC – 2M

Model	Connector	Cable material	Cable length
M83	M8, 3 Pin	SFSM: Straight female - Straight male	PVC: ø3.5 PVC
		SFW: Straight female - Lead wire	2M: 2000 mm
M84	M8, 4 Pin	LFW: Angle female - Lead wire	PUR: ø4.5 PUR
			5M: 5000 mm
M88	M8, 8 Pin	SFW: Straight female - Lead wire	PVC: ø5 PVC
			0.45M: 450 mm

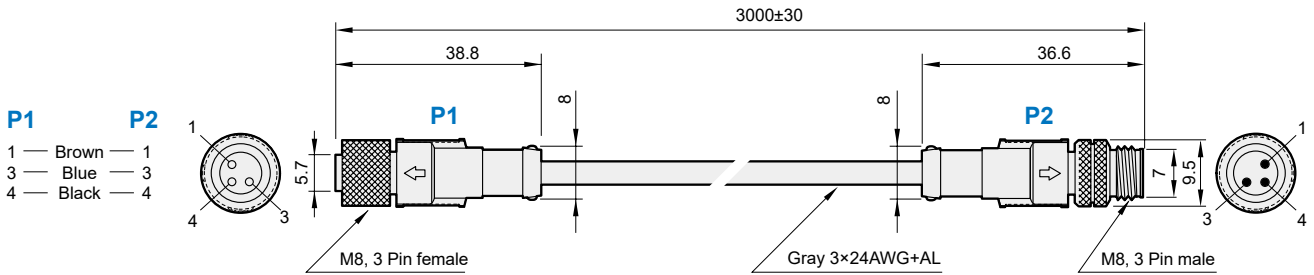
M8* Dimensions



CABLE WITH CONNECTOR (FEMALE – MALE / LEAD WIRE)


mindman

M83-SFSM




M83/M84-SFW

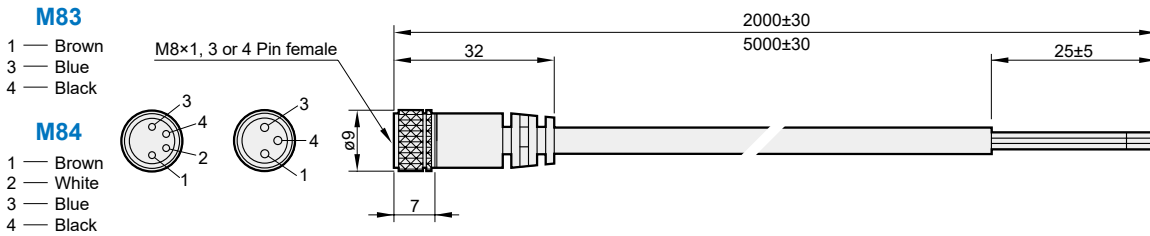Straight cable socket



M83/M84-LFW

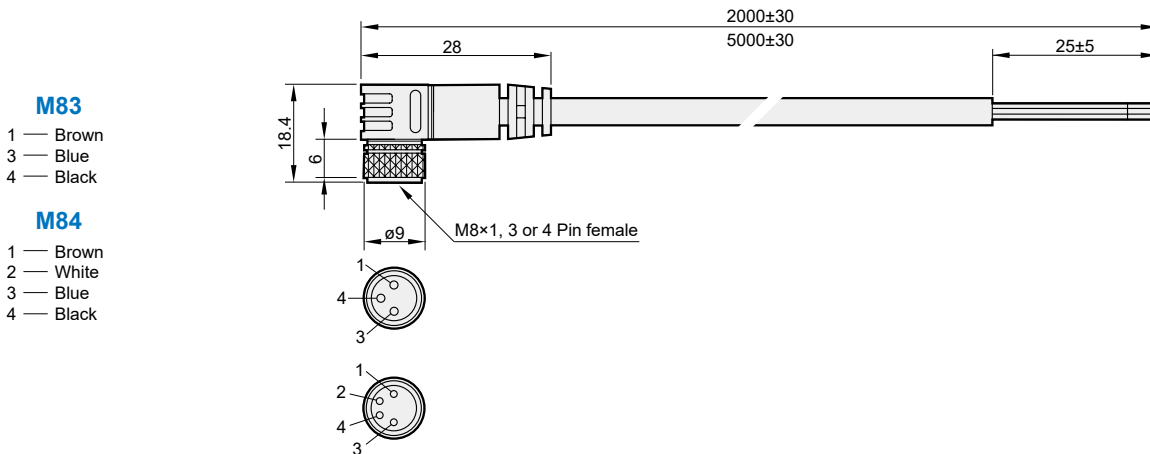Angle cable socket



M88-SFW

