 


MAF300 series

AIR UNIT (FILTER)



Symbol




Specification

Model	MAF300	
Bore No.	8A	10A
Port size	1/4	3/8
Medium	Air	
Operating pressure range (*)	0.05~1 MPa	
Proof pressure	1.5 MPa	
Ambient temperature	- 5~+60°C (No freezing)	
Filter element	Standard: 5μm, Option: 40μm	
Drain capacity	30 cm ³	
Weight	300 g	

* Standard unit contains semi-auto-drain function when operating pressure below 0.05 MPa.

Order example

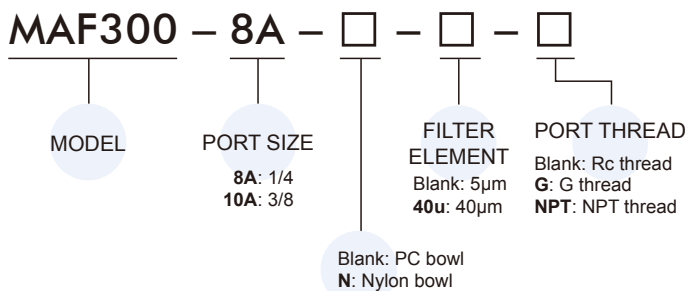

Flow feature

