

MAL510 series Stainless steel #316 type

 
AIR UNITS (L.UNIT)



Mindman



Symbol



Specification

Model	MAL510	
Bore No.	20A	25A
Port size	3/4	1
Medium	Air	
Max. operating pressure	1 MPa	
Proof pressure	1.5 MPa	
Ambient temperature	-5~+60°C (No freezing)	
Lubricating oil capacity	340 c.c	
Min. flow for oil drip	190 ℓ/min	
Recommended lubricating oil	Turbine oil ISO-VG32	
Weight	3350 g	

Order example

MAL510 - 20A - □




MODEL

BORE SIZE

20A : 3/4
25A : 1

PORT THREAD

Blank: Rc thread
G: G thread
NPT: NPT thread

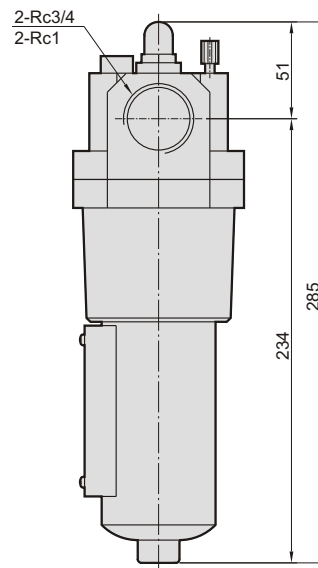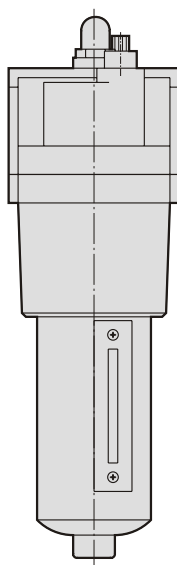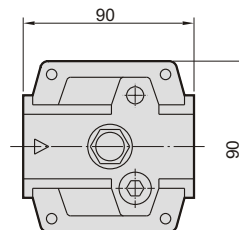

Mindman