


# MAR310 series Stainless steel #316 type

 
AIR UNITS (R. UNIT)

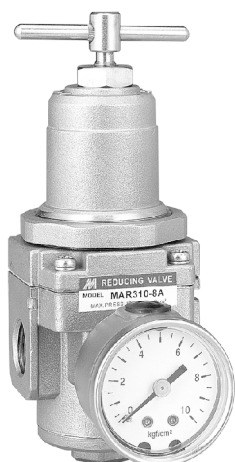

mindman



## Symbol



## Specification

| Model                    | MAR310                  |     |
|--------------------------|-------------------------|-----|
| Bore No.                 | 8A                      | 10A |
| Port size                | 1/4                     | 3/8 |
| Medium                   | Air                     |     |
| Max. operating pressure  | 1 MPa                   |     |
| Proof pressure           | 1.5 MPa                 |     |
| Regulated pressure range | 0.05~0.85 MPa           |     |
| Ambient temperature      | -5~+60°C (No freezing)  |     |
| Attachment               | Bracket, Pressure gauge |     |
| Weight                   | 1000 g                  |     |




## Order example

MAR310 — 8A — □

MODEL

BORE SIZE  
8A : 1/4  
10A : 3/8

PORT THREAD  
Blank: Rc thread  
G: G thread  
NPT: NPT thread

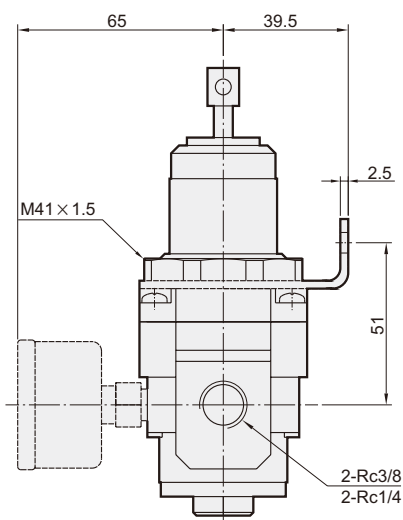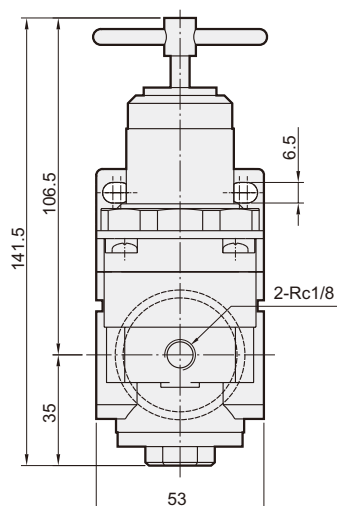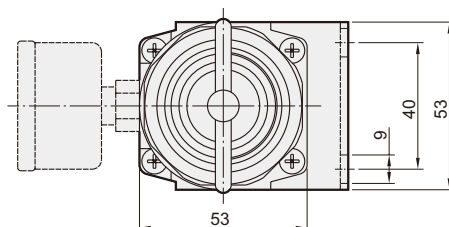

mindman