

MATFR401 series

AIR UNIT (F.R.UNIT)



Mindman



Selection table



Precision filter



 
User manual



Caution for safety
(Read before installing)



Symbol



Order example

MATFR401 - 8A - □ - HA□□ - E1 - B - □

MODEL

PORT SIZE

8A: 1/4
10A: 3/8
15A: 1/2

EXTERIOR
COLOR

Blank: Black & silver
W: Gray & white

PRESSURE SWITCH

Blank: without
E1: MP41P-022
E2: MP41P-022-QD**
E5: MP41P-042
E6: MP41P-042-QD**

** MOQ required.
Please contact us.

* Refer MP41 series

BRACKET


Blank: L type
B: C type

PORT THREAD

Blank: Rc thread
G: G thread
NPT: NPT thread

Option accessories

C type bracket

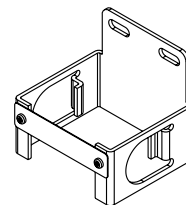


Type	Pressure gauge	Drain valve	Flow direction
Blank: Standard type	Blank: Pressure gauge (PG-20) C: External pressure gauge (PG-40) + Gauge adapter set (A-MAR401) A: Gauge adapter set (A-MAR401)	Blank: Semi-auto D: Auto (FMRF300)	Blank: Left to right R: Right to left
H: High pressure type	C: External pressure gauge (PG-40) + Gauge adapter set (A-MAR401) A: Gauge adapter set (A-MAR401)	Blank: Semi-auto	

* PG-40 (C), A-MAR302 (A) and MP41 (E*) can not be selected at the same time.

* Specification (W) gauge adapter set (A-MAR302).

MATFR401

L type bracket

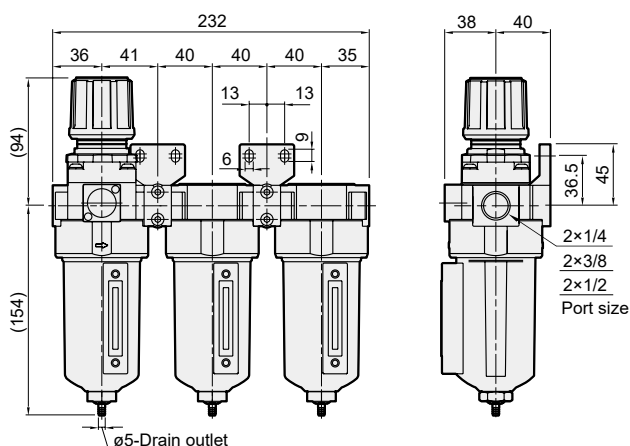

MATFR401-B

C type bracket

