
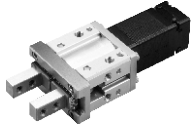


MEHC Inquiry sheet

ELECTRIC GRIPPER (WITH MOTOR)

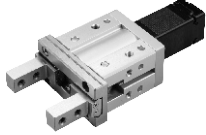

Mindman

MEHC inquiry sheet					
Customer		Register date		Register person	
Specification	Light loading 		Initial order code		
	<input type="checkbox"/> MEHC-20 series				
	Light loading 				
		<input type="checkbox"/> MEHC-25 series			
Control mode	<input type="checkbox"/> I/O <input type="checkbox"/> Pulse <input type="checkbox"/> Communication		Cable wire length		
I/O wire	<input type="checkbox"/> Ribbon cable <input type="checkbox"/> Stranded conductor (optional)		Feedback (optional)	<input type="checkbox"/> TTL <input type="checkbox"/> Differential signaling	
Needs	Stroke (mm): _____ Payload (kg): _____ Speed (mm/s): _____ Repeatability accuracy (mm): _____				
Clamping objects					
Working Environment	<input type="checkbox"/> General environment <input type="checkbox"/> Clean room(Class10) <input type="checkbox"/> Clean room(Class100)				
Using brand			Estimate Qty (annual)		
Remarks					

※ Fill out the form and contact the nearest Mindman sales office or distributor.



Mindman