
 
 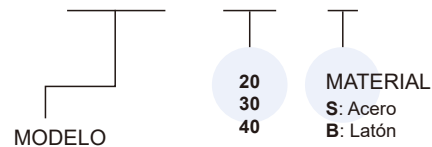
 





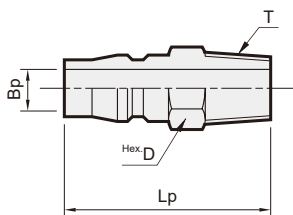
Ejemplo de pedido

MPM — 20 — S




MPM	
MPF	
MPH	
MPP	


MPM (rosca macho)




MPF (rosca hembra)

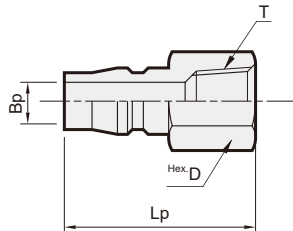

MPH (Conector de manguera)

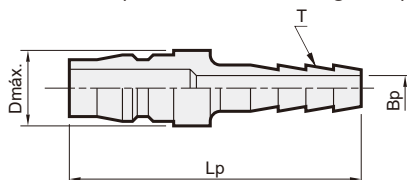

MPP (estilo tuerca)

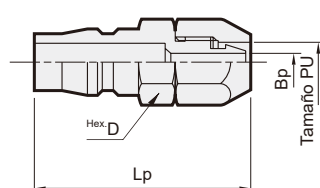

Modelo	Tuerca tornillo T	Dimensiones (mm)			Peso (g)	
		Bp	Hex. D	Lp	Acero	Latón
MPM-20	R1/4	ø7.5	Hex. 14/16.2	41	25	27
MPM-30	R3/8	ø7.5	Hex. 17/19.6	43	40	45
MPM-40	R1/2	ø7.5	Hex. 21/24.2	46	65	70

Modelo	Tuerca tornillo T	Dimensiones (mm)			Peso (g)	
		Bp	Hex. D	Lp	Acero	Latón
MPF-20	Rc1/4	ø7.5	Hex. 17/19.6	38	30	32
MPF-30	Rc3/8	ø7.5	Hex. 21/24.2	41	45	48
MPF-40	Rc1/2	ø7.5	Hex. 26/30	43	65	70

Modelo	Manguera tornillo T	Dimensiones (mm)			Peso (g)	
		Bp	D máx.	Lp	Acero	Latón
MPH-20	5/16»tubo	ø5	ø16	58	27	29
MPH-30	3/8»tubo	ø7.5	ø16	62	35	38
MPH-40	1/2»tubo	ø7.5	ø18	64	50	55

Modelo	Tamaño tamaño DI×DE (mm)	Dimensiones (mm)			Peso (g)	
		Bp	Hex. D	Lp	Acero	Latón
MPP-20	5×8	ø4	Hex. 14/16.2	42.5	30	33
MPP-30	6.5×10	ø5	Hex. 16/18.2	44.5	40	43
MPP-40	8×12	ø6	Hex. 17/19.2	45	40	43