



MSM

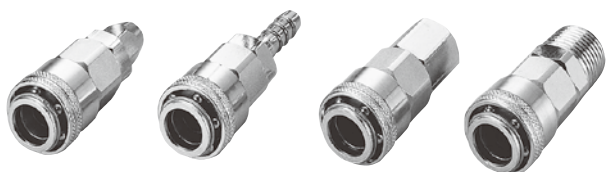


MSM-A (con bloqueo)




MSM (Tornillo macho)

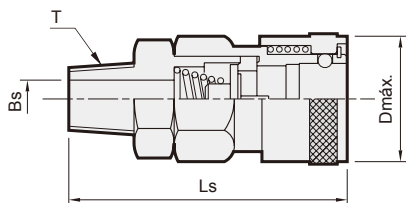


MSF (Tornillo hembra)

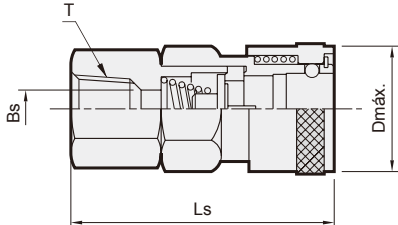

MSH (Conector de manguera)

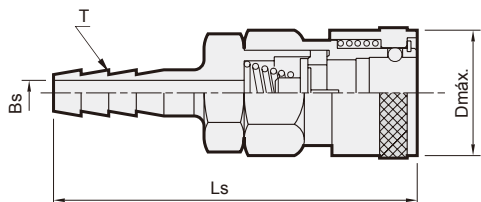


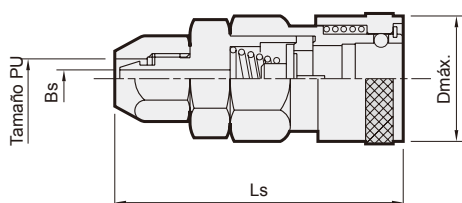



MSP (estilo tuerca)



Ejemplo de pedido

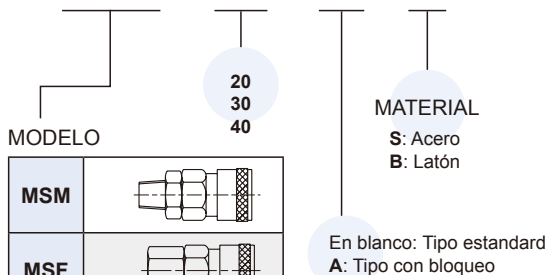MSM — 20 — A — S

 

MSM	
MSF	
MSH	
MSP	

Modelo	Tuerca tornillo T	Dimensiones (mm)			Peso (g)	
		Bs	D máx.	Ls	Acero	Latón
MSM-20	R1/4	ø7.5	ø25	55.5	95	104
MSM-30	R3/8	ø7.5	ø25	57.5	100	109
MSM-40	R1/2	ø9	ø25	59.5	110	117

Modelo	Tuerca tornillo T	Dimensiones (mm)			Peso (g)	
		Bs	D máx.	Ls	Acero	Latón
MSF-20	Rc1/4	ø7.5	ø25	52.5	104	110
MSF-30	Rc3/8	ø7.5	ø25	54.5	103	111
MSF-40	Rc1/2	ø9	ø25	54.5	122	131

Modelo	Manguera tornillo T	Dimensiones (mm)			Peso (g)	
		Bs	D máx.	Ls	Acero	Latón
MSH-20	5/16»tubo	ø5	ø25	72.5	95	104
MSH-30	3/8»tubo	ø7.5	ø25	76.5	100	106
MSH-40	1/2»tubo	ø9	Hex 26/30	78.5	110	117

Modelo	Tamaño tamaño DI×DE (mm)	Dimensiones (mm)			Peso (g)	
		Bs	D máx.	Ls	Acero	Latón
MSP-20	5×8	ø4	ø25	56.5	100	106
MSP-30	6.5×10	ø5	ø26	58	110	116
MSP-40	8×12	ø6	ø26	59	110	116